


1064 nm Fixed Narrowband, 0.3 W

ITEM #	IO-2.5-1064-VLP
Type	Fixed Narrowband
Center Wavelength	1064 nm
Tuning Range	N/A
Operating Range	1058 - 1084 nm
Transmission	76%
Typ. Isolation (Min)	40 dB (34 dB)
Max Beam Diameter	2.3 mm
Optical Axis Height*	0.63"
Max Power	0.3 W
Max Power Density	10 W/cm ²
Isolator OD x L**	Ø0.56" x 0.49"

*Mounted as shown in image

**OD of main isolator housing, L = total length of the isolator

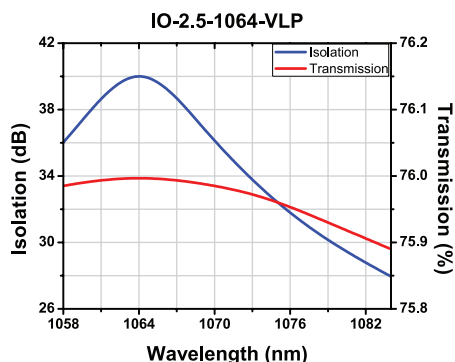

IO-2.5-1064-VLP


ITEM #	\$	£	€	RMB	DESCRIPTION
IO-2.5-1064-VLP	\$ 675.00	£ 486.00	€ 587,25	¥ 5,379.75	1064 nm Fixed Narrowband Isolator, 0.3 W (Max) Power

1064 nm Fixed Narrowband, 0.45 W

ITEM #	IO-2.5E-1064-VLP
Type	Fixed Narrowband
Center Wavelength	1064 nm
Tuning Range	N/A
Operating Range	1058 - 1084 nm
Transmission	86%
Typ. Isolation (Min)	34 dB (28 dB)
Max Beam Diameter	2.3 mm
Optical Axis Height*	0.75"
Max Power	0.45 W
Max Power Density	25 W/cm ²
Isolator OD x L**	Ø0.87" x 1.25"

*Mounted as shown in image

**OD of main isolator housing, L = total length of the isolator

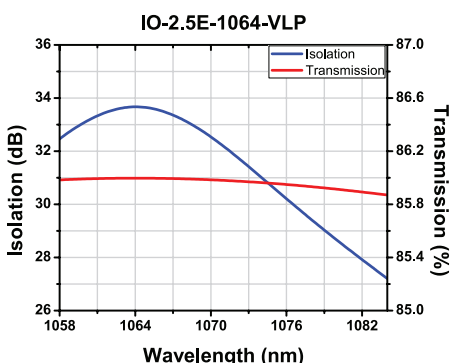

IO-2.5E-1064-VLP
1.50" x 1.50" Base


ITEM #	\$	£	€	RMB	DESCRIPTION
IO-2.5E-1064-VLP	\$ 1,430.00	£ 1,029.60	€ 1,244,10	¥ 11,397.10	1064 nm Fixed Narrowband Isolator, 0.45 W (Max) Power

1064 nm Fixed Narrowband, 0.7 W

ITEM #	IO-3D-1064-VLP
Type	Fixed Narrowband
Center Wavelength	1064 nm
Tuning Range	N/A
Operating Range	1058 - 1084 nm
Transmission	90%
Typ. Isolation (Min)	44 dB (38 dB)
Max Beam Diameter	2.7 mm
Optical Axis Height*	0.75"
Max Power	0.7 W
Max Power Density	25 W/cm ²
Isolator OD x L**	Ø1.23" x 2.00"

*Mounted as shown in image

**OD of main isolator housing, L = total length of the isolator

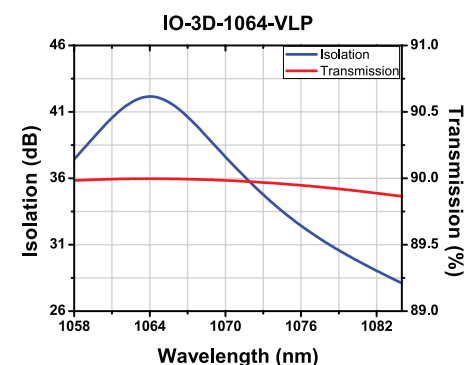

Mechanical
Drawings Available on the
WEB



IO-3D-1064-VLP

ITEM #	\$	£	€	RMB	DESCRIPTION
IO-3D-1064-VLP	\$ 1,625.00	£ 1,170.00	€ 1,413,75	¥ 12,951.25	1064 nm Fixed Narrowband Isolator, 0.7 W (Max) Power

1064 nm
Fiber
Isolators



See Page
1123