


1310 nm Adjustable Narrowband, 1.2 W

ITEM #	IO-4-1310-VLP
Type	Adjustable Narrowband
Center Wavelength	1310 nm
Tuning Range	1275 - 1350 nm
Operating Range	1250 - 1375 nm
Transmission	95%
Typ. Isolation (Min)	42 dB (38 dB)
Max Beam Diameter	3.6 mm
Optical Axis Height*	0.75"
Max Power	1.2 W
Max Power Density	25 W/cm ²
Isolator OD x L**	Ø0.87" x 0.60"

*Mounted as shown in image

**OD of main isolator housing, L = total length of the isolator

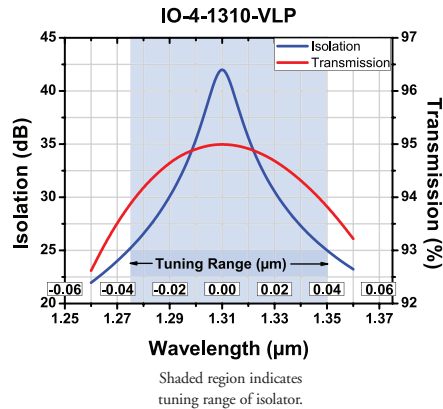

IO-4-1310-VLP
1.50" x 1.50" Base


ITEM #	\$	£	€	RMB	DESCRIPTION
IO-4-1310-VLP	\$ 850.00	£ 612.00	€ 739,50	¥ 6,774.50	1310 nm Adjustable Narrowband Isolator, 1.2 W (Max) Power

1550 nm Fixed Narrowband, 0.2 W

ITEM #	IO-D-1550-VLP
Type	Fixed Narrowband
Center Wavelength	1550 nm
Tuning Range	N/A
Operating Range	1500 - 1600 nm
Transmission	95%
Typ. Isolation (Min)	40 dB (36 dB)
Max Beam Diameter	1.6 mm
Optical Axis Height*	0.11"
Max Power	0.2 W
Max Power Density	25 W/cm ²
Isolator OD x L**	Ø0.22" x 0.16"

*Mounted as shown in image

**OD of main isolator housing, L = total length of the isolator

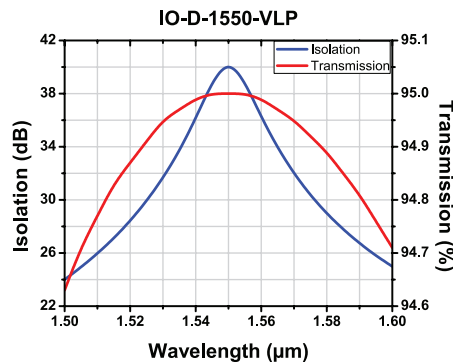

Mechanical
Drawings Available on the
WEB



IO-D-1550-VLP


ITEM #	\$	£	€	RMB	DESCRIPTION
IO-D-1550-VLP	\$ 495.00	£ 356.40	€ 430,65	¥ 3,945.15	1550 nm Fixed Narrowband Isolator, 0.2 W (Max) Power

1550 nm Fixed Narrowband, 0.4 W

ITEM #	IO-2.5-1550-VLP
Type	Fixed Narrowband
Center Wavelength	1550 nm
Tuning Range	N/A
Operating Range	1500 - 1600 nm
Transmission	95%
Typ. Isolation (Min)	43 dB (38 dB)
Max Beam Diameter	2.3 mm
Optical Axis Height*	0.63"
Max Power	0.4 W
Max Power Density	25 W/cm ²
Isolator OD x L**	Ø0.50" x 0.49"

*Mounted as shown in image

**OD of main isolator housing, L = total length of the isolator

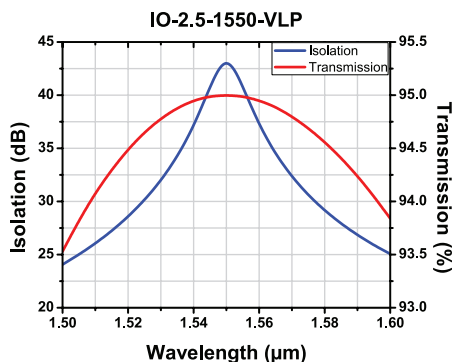

IO-2.5-1550-VLP

ITEM #	\$	£	€	RMB	DESCRIPTION
IO-2.5-1550-VLP	\$ 700.00	£ 504.00	€ 609,00	¥ 5,579.00	1550 nm Fixed Narrowband Isolator, 0.4 W (Max) Power

