


SM1-Threaded Mounted Visible Achromatic Doublets

- Holds Ø25.4 mm Achromatic Doublets
- Cell Engraved with Part Number, Focal Length, and Coating

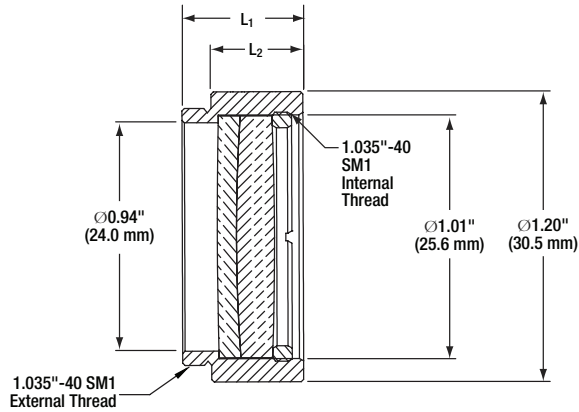


ITEM #	D* (mm)	f (mm)	L ₁ (mm)	L ₂ (mm)	MATERIALS	\$	£	€	RMB
AC254-030-A-ML	25.4	30	0.68	0.56	N-BAF10/N-SF6HT	\$ 97.00	£ 69.84	€ 84.39	¥ 773.09
AC254-035-A-ML	25.4	35	0.68	0.56	N-BAF10/N-SF6HT	\$ 97.00	£ 69.84	€ 84.39	¥ 773.09
AC254-040-A-ML	25.4	40	0.61	0.49	N-BK7/SF5	\$ 91.30	£ 65.74	€ 79.43	¥ 727.66
AC254-045-A-ML	25.4	45	0.56	0.44	N-BAF10/N-SF6HT	\$ 91.30	£ 65.74	€ 79.43	¥ 727.66
AC254-050-A-ML	25.4	50	0.68	0.56	N-BAF10/SF10	\$ 91.30	£ 65.74	€ 79.43	¥ 727.66
AC254-060-A-ML	25.4	60	0.61	0.49	E-BAF11/FD10	\$ 91.30	£ 65.74	€ 79.43	¥ 727.66
AC254-075-A-ML	25.4	75	0.56	0.44	N-BK7/SF5	\$ 91.30	£ 65.74	€ 79.43	¥ 727.66
AC254-100-A-ML	25.4	100	0.50	0.38	N-BK7/SF5	\$ 91.30	£ 65.74	€ 79.43	¥ 727.66
AC254-150-A-ML	25.4	150	0.56	0.44	N-BK7/SF5	\$ 91.30	£ 65.74	€ 79.43	¥ 727.66
AC254-200-A-ML	25.4	200	0.50	0.38	N-SSK5/LAFN7	\$ 91.30	£ 65.74	€ 79.43	¥ 727.66
AC254-250-A-ML	25.4	250	0.50	0.38	N-BK7/SF2	\$ 91.30	£ 65.74	€ 79.43	¥ 727.66
AC254-300-A-ML	25.4	300	0.50	0.38	N-BK7/SF2	\$ 91.30	£ 65.74	€ 79.43	¥ 727.66
AC254-400-A-ML	25.4	400	0.50	0.38	N-BK7/SF2	\$ 91.30	£ 65.74	€ 79.43	¥ 727.66
AC254-500-A-ML	25.4	500	0.50	0.38	N-BK7/SF2	\$ 91.30	£ 65.74	€ 79.43	¥ 727.66

*Diameter of Unmounted Lens

SM2-Threaded Mounted Visible Achromatic Doublets

- Holds Ø50.8 mm Achromatic Doublets
- Cell Engraved with Part Number, Focal Length, and Coating

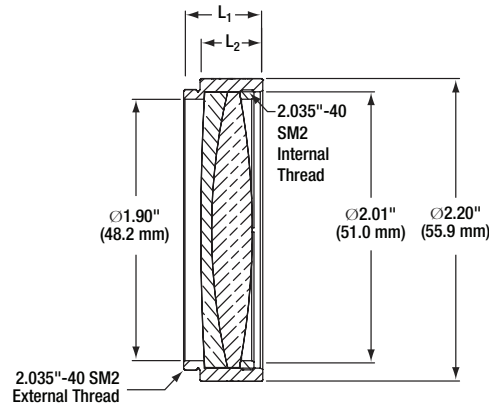

ITEM #	D* (mm)	f (mm)	L ₁ (mm)	L ₂ (mm)	MATERIALS	\$	£	€	RMB
AC508-075-A-ML	50.8	75	0.92	0.80	E-BAF11/N-SF11	\$ 143.10	£ 103.03	€ 124.50	¥ 1,140.51
AC508-080-A-ML	50.8	80	0.75	0.63	N-BAF10/N-SF6HT	\$ 143.10	£ 103.03	€ 124.50	¥ 1,140.51
AC508-100-A-ML	50.8	100	0.92	0.80	N-BAF10/SF10	\$ 127.90	£ 92.09	€ 111.27	¥ 1,019.36
AC508-150-A-ML	50.8	150	0.75	0.63	N-BK7/SF5	\$ 127.90	£ 92.09	€ 111.27	¥ 1,019.36
AC508-200-A-ML	50.8	200	0.58	0.46	N-BK7/SF2	\$ 127.90	£ 92.09	€ 111.27	¥ 1,019.36
AC508-250-A-ML	50.8	250	0.58	0.46	N-BK7/SF2	\$ 127.90	£ 92.09	€ 111.27	¥ 1,019.36
AC508-300-A-ML	50.8	300	0.58	0.46	N-BK7/SF2	\$ 127.90	£ 92.09	€ 111.27	¥ 1,019.36
AC508-400-A-ML	50.8	400	0.58	0.46	N-BK7/SF2	\$ 127.90	£ 92.09	€ 111.27	¥ 1,019.36
AC508-500-A-ML	50.8	500	0.58	0.46	N-BK7/SF2	\$ 127.90	£ 92.09	€ 111.27	¥ 1,019.36
AC508-750-A-ML	50.8	750	0.58	0.46	N-BK7/SF2	\$ 127.90	£ 92.09	€ 111.27	¥ 1,019.36
AC508-1000-A-ML	50.8	1000	0.58	0.46	N-BK7/SF2	\$ 127.90	£ 92.09	€ 111.27	¥ 1,019.36

*Diameter of Unmounted Lens